



Decento®

They say that the best view in the world is between a horse's ears. In your own horse you find a soul mate. A horse and a hound are noble companions. Just like Decento®. The porcelain original.



—
white



—
white / natural beech



—
white / cherry wood



—
black



Decento®

Installation instructions for creating multiple combinations

Decento switches and socket outlets - eye-catching in any interior. And because the porcelain Decento® is designed to create a period theme, multiple combination inserts can be placed side by side or one above the other. This does even more to accentuate the originality of the design.


Box spacers for precise installation

For a perfect fit with individual inserts in combinations, the spacing between central point of insert installation boxes must be 91 mm. For these assemblies we recommend the use of Kaiser Co. installation boxes, order





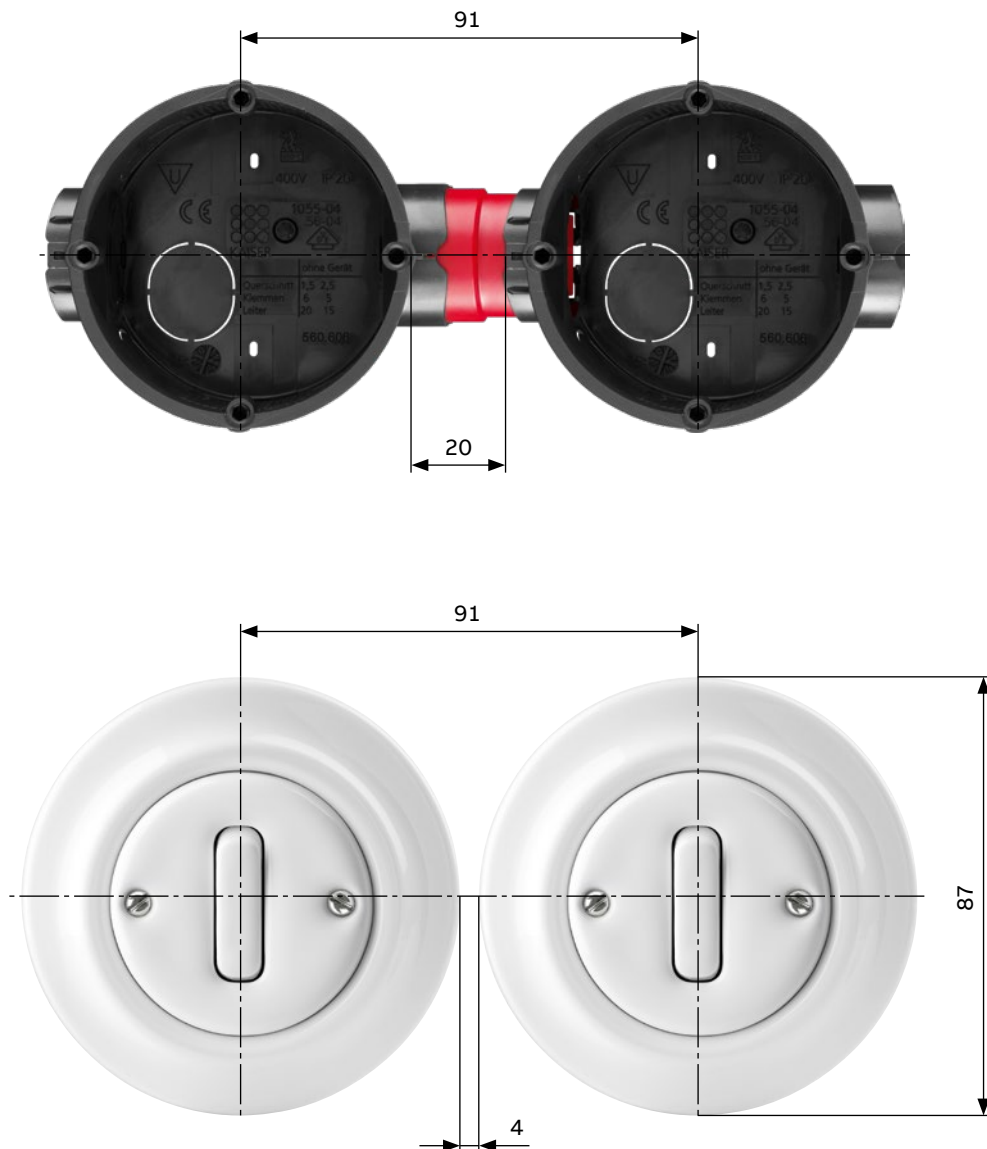


no. 1155-41, which have snap-on spacers, order no. 1159-34 (see page 114). These allow perfect spacing between the central points of installation boxes and single cover frames of Decento® switches and socket outlets every time.

Place a spacers between two boxes.

91 mm spacing between central points of installation boxes is recommended for flush mounting both in solid walls and hollow walls or partitions.










Decento® Switches

| Connection type | Name | Colour | Order number | Pack/Min. Qty | |
|------------------|---|--|--|------------------|---|
| For range | Technical data | | | | Completeness |
| 6 | Rotary switch 1gang 2way ³⁾ | white white / natural beech white / cherry wood black | 3560K-C06345 3560K-C06345 50 3560K-C06345 52 3560K-C06345 N | 1 1 1 1 |  |
| Decento® | Screwless terminals. 10 A, 250 V AC | | | | 1 2 3 4 5 6 7 8 |
| 7 | Rotary intermediate switch ³⁾ | white white / natural beech white / cherry wood black | 3560K-C07345 3560K-C07345 50 3560K-C07345 52 3560K-C07345 N | 1 1 1 1 |  |
| Decento® | Screwless terminals. 10 A, 250 V AC | | | | 1 2 3 4 5 6 7 8 |
| 6 | Rocker switch 1gang 2way ³⁾ | white white / natural beech white / cherry wood black | 3559K-C06345 3559K-C06345 50 3559K-C06345 52 3559K-C06345 N | 1 1 1 1 |  |
| Decento® | Screwless terminals. 10 AX, 250 V AC | | | | 1 2 3 4 5 6 7 8 |
| 7 | Rocker intermediate switch ³⁾ | white white / natural beech white / cherry wood black | 3559K-C07345 3559K-C07345 50 3559K-C07345 52 3559K-C07345 N | 1 1 1 1 |  |
| Decento® | Screwless terminals. 10 AX, 250 V AC | | | | 1 2 3 4 5 6 7 8 |
| 5 | Rocker switch 2gang 1way ³⁾ | white white / natural beech white / cherry wood black | 3559K-C05345 3559K-C05345 50 3559K-C05345 52 3559K-C05345 N | 1 1 1 1 |  |
| Decento® | Screwless terminals. 10 AX, 250 V AC | | | | 1 2 3 4 5 6 7 8 |
| 6/0 | Rocker push-switch 1gang 2way, with N terminal ³⁾ | white white / natural beech white / cherry wood black | 3559K-C86345 3559K-C86345 50 3559K-C86345 52 3559K-C86345 N | 1 1 1 1 |  |
| Decento® | Screwless terminals. 10 A, 250 V AC | | | | 1 2 3 4 5 6 7 8 |
| 1/0+1/0 | Rocker push-switch 2gang 1way (separated circuits) ³⁾ | white white / natural beech white / cherry wood black | 3559K-C87345 3559K-C87345 50 3559K-C87345 52 3559K-C87345 N | 1 1 1 1 |  |
| Decento® | Screwless terminals. 10 A, 250 V AC | | | | 1 2 3 4 5 6 7 8 |

Notes:

³⁾ A neon lamp or LED cannot be used.

When installing multiple inserts horizontally or vertically, the spacing between the central points of installation boxes must be at least 91 mm.







| | Connection type | Name | Colour | Order number | Pack/Min. Qty |
|---|--|--|--|--|------------------|
|  | For range | Technical data | | Completeness | |
| | 6+6 (6+1) | Rocker switch 2gang 2way | white white / natural beech white / cherry wood black | 3559K-C52345 3559K-C52345 50 3559K-C52345 52 3559K-C52345 N | 1 1 1 1 |
| Decento® | | Screwless terminals. 10 AX / 10 A, 250 V AC | | 1 2 3 4 5 6 7 8 | |
|  | 1/0+1/0 with interlock | Rocker blind push-switch 2gang 1way | white white / natural beech white / cherry wood black | 3559K-C88345 3559K-C88345 50 3559K-C88345 52 3559K-C88345 N | 1 1 1 1 |
| | Decento® | Screwless terminals. 10 A, 250 V AC | | 1 2 3 4 5 6 7 8 | |
|  | TV+R+SAT | Radio/TV/SAT coaxial outlets, terminal type | white white / natural beech white / cherry wood black | 5011K-C00403 5011K-C00403 50 5011K-C00403 52 5011K-C00403 N | 1 1 1 1 |
| | Decento® | Allows current passage of 500 mA DC and a 22 kHz signal for LNB power supply and control. Nominal impedance of inputs and outputs: 75 Ω For coaxial cables with a diameter of 3.6 to 6.8 mm. A subscriber cord with a straight connector is recommended. Fixation via screws or claws. Technical data – see page 285. Insert article number: EU 3303 | | 1 2 3 4 5 6 7 8 | |
|  | RJ45C5U RJ45C6U RJ45C5S RJ45C6AS 1116412-3 | Communication double socket outlet | white white / natural beech white / cherry wood black | 5014K-C01018 5014K-C01018 50 5014K-C01018 52 5014K-C01018 N | 1 1 1 1 |
| | Decento® | Comprising mounting plate and base with 2 entries (15.4 mm spacing) to hold two Modular-Jack communication inserts (keystone) or dummy plug (max. recommended width 18.3 mm). Entry dimensions: 19,4 × 14,8 mm The base is also suitable for keystone inserts by AMP, Panduit and other firms. | | 1 2 3 4 5 6 7 8 | |
|  | 5014K-C01018 .. | Dummy plug for communication socket outlet | grey | 1116412-3 | 25 |
| Decento® | | | | 1 2 3 4 5 6 7 8 | |
|  | | Stereo speaker outlet ²⁵⁾ | white black | 5014K-C00404 5014K-C00404 N | 1 1 |
| | Decento® | Screwless connection of speaker wires (spring-loaded terminals). Screw terminals for connecting wires from amplifier. The polarity of the conductors is colour-coded. Conductor cross-section: max. 10 mm ² Screw and claw fixation. Insert article number: 0248/0x-101 | | 1 2 3 4 5 6 7 8 | |
|  | | HDMI communications socket ²⁵⁾ | white black | 5014K-C00432 5014K-C00432 N | 1 1 |
| | Decento® | With strain relief clamp. For transmitting digital video and audio signals with a HDMI high definition cable. 1 HDMI type A outlet. Screw connection for 20-pin HDMI cable. Installation depth: 34 mm The maximum cable length and bending radii must be observed recommended by the manufacturer of the cable or device. Insert article number: 0261/33-500 | | 1 2 3 4 5 6 7 8 | |

Notes:

²⁵⁾ The cover is made of plastic.

⊗ Product may not be in stock; delivery is within 3 weeks at the latest.

When installing multiple inserts horizontally or vertically, the spacing between the central points of installation boxes must be at least 91 mm.

| Connection type | Name | Colour | Order number | Pack/Min. Qty | |
|------------------|--|--|---|------------------|---|
| For range | Technical data | | Completeness | | |
| | <p>USB communications socket ²⁵⁾</p> <p>With strain relief clamp. For communication mobile end devices using USB cable. 1 USB 2.0 type A outlet. Screw connection for 5-pin USB cable. Installation depth: 34 mm The maximum cable length and bending radii must be observed recommended by the manufacturer of the cable or device. Insert article number: 0261/13-500</p> | white black | <p>🔌 5014K-C00420</p> <p>🔌 5014K-C00420 N</p> | 1 1 |  |
| Decento® | | | 1 2 3 4 5 6 7 8 | | |
| | <p>VGA connection socket ²⁵⁾</p> <p>With strain relief clamp. For analogue transmission video signal using a VGA cable. For connecting an analogue display device (monitor) to a computer (PC, notebook, laptop). 1 VGA type D outlet. Screw connection for 15-pin VGA cable. Installation depth: 34 mm The maximum cable length and bending radii must be observed recommended by the manufacturer of the cable or device. Insert article number: 0261/23-500</p> | white black | <p>🔌 5014K-C00426</p> <p>🔌 5014K-C00426 N</p> | 1 1 |  |
| Decento® | | | 1 2 3 4 5 6 7 8 | | |
| | <p>USB power adapter insert ²⁵⁾</p> <p>For charging and powering mobile devices using USB cable. 2 USB type A socket outlets for charging up to two devices with a standard charging interface pursuant to EN 62684. Short-circuit and overload electronic protection. Output voltage: 5 V DC ±5 % (SELV) Rated current using one socket outlet: 1 400 mA Rated current using both socket outlets: 2× 700 mA Standby consumption: 0.3 W Cannot be used for data transfer. The insert is also compatible with Apple products iPod/iPhone/iPad. Operating temperature: +5 °C to +40 °C Protection class: IP 20 Installation depth: 32 mm Insert article number: 6472 U-500 2 wire connection, 230 V AC, 50/60 Hz</p> | white black | <p>5014K-C00002</p> <p>5014K-C00002 N</p> | 1 1 |  |
| Decento® | | | 1 2 3 4 5 6 7 8 | | |
| 2P+PE | <p>Blank cover plate ²⁵⁾</p> <p>With metal mounting plate.</p> | white black | <p>3902K-C00100</p> <p>3902K-C00100 N</p> | 1 1 |  |
| Decento® | | | 1 2 3 4 5 6 7 8 | | |
| 2P+PE | <p>Socket outlet with earthing pin</p> <p>Screwless terminals. Fixation via screws only. 16 A, 250 V AC</p> | white white / natural beech white / cherry wood black | <p>5519K-C02347</p> <p>5519K-C02347 50</p> <p>5519K-C02347 52</p> <p>5519K-C02347 N</p> | 1 1 1 1 |  |
| Decento® | | | 1 2 3 4 5 6 7 8 | | |
| 2P+PE | <p>Socket outlet with earthing pin, shuttered ²⁵⁾</p> <p>Screwless terminals. Fixation via screws only. 16 A, 250 V AC</p> | white white / natural beech white / cherry wood black | <p>5519K-C02357</p> <p>5519K-C02357 50</p> <p>5519K-C02357 52</p> <p>5519K-C02357 N</p> | 1 1 1 1 |  |
| Decento® | | | 1 2 3 4 5 6 7 8 | | |

Notes:





²⁵⁾ The cover is made of plastic.

🔌 Product may not be in stock; delivery is within 3 weeks at the latest.

When installing multiple inserts horizontally or vertically, the spacing between the central points of installation boxes must be at least 91 mm.

Decento®

Sockets • Boxes

| | Connection type | Name | Colour | Order number | Pack/Min. Qty |
|---|--|---|--|--|---------------|
|  | 2P+PE (DIN standard) | Socket outlet with earthing contacts ²⁵⁾ Screwless terminals. Fixation via screws only. 16 A, 250 V AC | white white / natural beech white / cherry wood black | Completeness | |
| | | | | 5520K-C03449 | 1 |
| | | | | 5520K-C03449 50 | 1 |
| | | | | 5520K-C03449 52 | 1 |
| | | | | 5520K-C03449 N | 1 |
| Decento® 1 2 3 4 5 6 7 8 | | | | | |
|  | 2P+PE (DIN standard) | Socket outlet with earthing contacts, shuttered ²⁵⁾ Screwless terminals. Fixation via screws only. 16 A, 250 V AC | white white / natural beech white / cherry wood black | Completeness | |
| | | | | 5520K-C03459 | 1 |
| | | | | 5520K-C03459 50 | 1 |
| | | | | 5520K-C03459 52 | 1 |
| | | | | 5520K-C03459 N | 1 |
| Decento® 1 2 3 4 5 6 7 8 | | | | | |
|  | | Universal box for installing multiple inserts When assembled, the spacing between the central points of boxes is 71 mm. Internal depth: 44 mm Depth of box: 46 mm | | 1055-41 | 10 |
| | Decento® | | | | |
| | | Article number: 1055-04 Decento® switch range inserts cannot be installed in a multiple frame. When installing multiple inserts horizontally or vertically, the spacing between the central points of installation boxes must be at least 91 mm. | | 1 2 3 4 5 6 7 8 | |
|  | | Box spacer For setting central points of 1055-41 boxes to 91 mm when installing multiple Decento® inserts. | | 1159-34 | 25/1 |
| | Decento® 1 2 3 4 5 6 7 8 | | | | |

Notes:

—
Notes

