

VR LED

Hazardous location remote fixture



CLASSIFICATION

CLASS I

Division 2

Groups A, B, C, D

Contact your ABB sales representative to verify classification

CERTIFICATIONS



LR111065

UL844
UL924



CERTIFIED
FOR U.S. ONLY

Key features and benefits

Description

- Available with single or double lamp heads
- Die-cast aluminum back plate with gasket
- Vandal-resistant UV stabilized polycarbonate lamp cover
- Comes standard with tamper-proof screws and bit
- Universal J-box mounting
- Extreme operational temperature range: 10 to 40°C (50 to 104°F)

Mounting

- Surface mount
- Conduit entry 1/2" NPT


Approval

- CSA-US (to UL 924 standards)
- Evaluated to the UL 844 Standard for Class I Division 2, Groups A, B, C and D

Warranty

- Five-year limited warranty

Dimensions

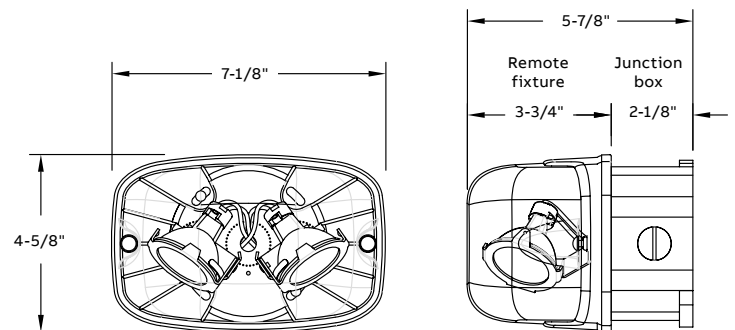

Lighting fixture

Part	Part number	Description
1 Series	VR	Single C1D2
	VRD	Double C1D2
2 Lamp type/wattage	L1	6V 4W, MR16 LED
	L2	6V 5W, MR16 LED
	L7	12V 4W, MR16 LED
	L9	12V 5W, MR16 LED
	L10	12V 6W, MR16 LED
	L13	24V 4W, MR16 LED
	L26	120V 4W, MR16 LED cw wires
3 Color	-G	Gray