


Serenga 2

Project covering & stylish



Escape route lighting

- Compatible with DALI control unit to control, test & monitor emergency lighting
- Injection moulded - high grade polycarbonate body and geartray of aluminium die cast
- Specially designed lens for optimised light distribution
- Modular, First-Fix installation

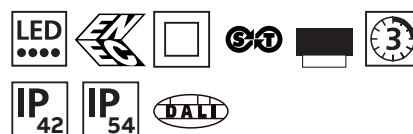

Luminaire


Order code	Description	Input voltage	Lamp type	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
DASR2-DEA-M3	REC M3 DALI ESC-4MH WH	220-240 Vac, 50 Hz	2x LED 0.85W = 1,9W	4.74 / 4.0	M3/NM3	5 - 40	0.6 kg
DASR2-DAD-M3	REC M3 DALI OA-L4M WH	220-240 Vac, 50 Hz	2x LED 0.85W = 1,9W	4.74 / 4.0	M3/NM3	5 - 40	0.6 kg
DASR2-SEM3-A1	SFC M3 DALI ESC-L4M WH	220-240 Vac, 50 Hz	2 x LED 0.85W = 1.9W	4.74 / 4.0	M3/NM3	5 - 40	1.0
DASR2-SAM3-D1	SFC M3 DALI OA-L4M WH	220-240 Vac, 50 Hz	2 x LED 0.85W = 1.9W	4.74 / 4.0	M3/NM3	5 - 40	1.0

Interchangeable lenses are available.
Maintained and non maintained

Accessories

Order code	Description
SR2-CCAW	WH circular adaptor

Picture table

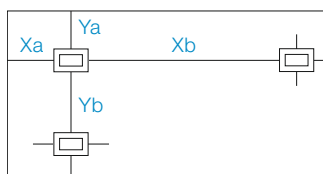

Spacing table

DASR2-DEA-M3						DASR2-DAD-M3						DASR2-SEM3-A1						DASR2-SAM3-D1					
h(m)	1.8	4.9	6.4	18.8		h(m)	3.5	7.8	3.5	7.8		h(m)	1.8	4.9	6.4	18.8		h(m)	3.5	7.8	3.5	7.8	
2.0	1.8	4.9	6.4	18.8		2.0	3.5	7.8	3.5	7.8		2.0	1.8	4.9	6.4	18.8		2.0	3.5	7.8	3.5	7.8	
2.5	1.3	5.3	6.4	19.4		2.5	4.3	9.4	4.3	9.4		2.5	1.3	5.3	6.4	19.4		2.5	4.3	9.4	4.3	9.4	
3.0	1.0	5.0	3.9	18.3		3.0	4.7	11.0	4.7	11.0		3.0	1.0	5.0	3.9	18.3		3.0	4.7	11.0	4.7	11.0	
3.5	0.9	3.9	3.6	16.6		3.5	4.4	12.2	4.4	12.2		3.5	0.9	3.9	3.6	16.6		3.5	4.4	12.2	4.4	12.2	
4.0	0.9	3.1	2.5	15.6		4.0	2.5	10.9	2.5	10.9		4.0	0.9	3.1	2.5	15.6		4.0	2.5	10.9	2.5	10.9	

