


EXLLH - High Temp Conduit LT Metallic Range

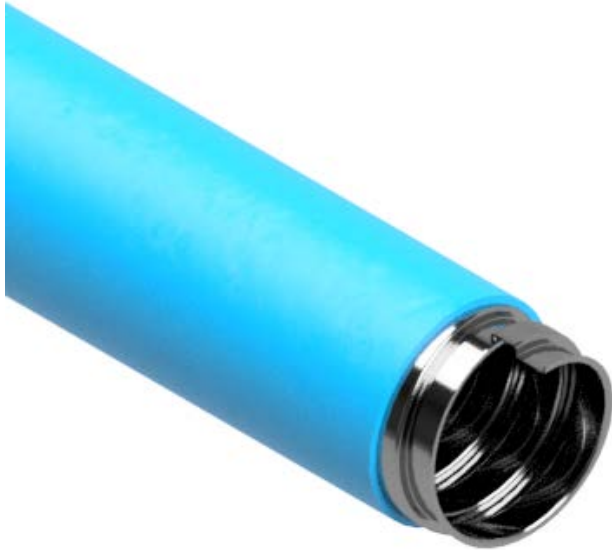

Material

- Co-Polyester Covering
- Galvanised Steel Core
- Cotton Packed (03-07)
- Interlocked (08-09)

Features

- Flame Resistant
- Chemical and Oil Resistant
- UL94 V2

Approvals



Certification & Standards

| | |
|--------------------------------|---|
| Approved to: | IEC61386-1, 61386-23 |
| Type Examination Certificates: | Must be used with HA-G1 fittings in approved Zones May be used with Ex LT fittings in safe areas |
| Temperature: | Static -50°C to +130°C Dynamic -5°C to +90°C |

Compatible with: EXQ*, EXS*, EXR*, HA-G1 Fittings / Colour: Blue

| Part No. | Conduit Size | | Static Bend Radius (mm) | Inside Diameter (mm) | Coil Length (m) | GiD Codes |
|----------|--------------|-----------------|-------------------------|----------------------|-----------------|-----------------------------------|
| | Metric (mm) | US Trade (Inch) | | | | |
| EXLLH03* | 16 | 3/8" | 50.0 | 12.5 | 10 / 30 | 7TCA297120R0116 - 7TCA297120R0118 |
| EXLLH04* | 20 | 1/2" | 75.0 | 16.0 | 10 / 30 | 7TCA297120R0119 - 7TCA297120R0121 |
| EXLLH05* | 25 | 3/4" | 90.0 | 21.0 | 10 / 30 | 7TCA297120R0122 - 7TCA297120R0124 |
| EXLLH06* | 32 | 1" | 110.0 | 26.4 | 10 / 20 | 7TCA297120R0125 - 7TCA297120R0126 |
| EXLLH07* | 40 | 1-1/4" | 130.0 | 35.3 | 10 / 20 | 7TCA297120R0127 - 7TCA297120R0128 |
| EXLLH08* | 50 | 1-1/2" | 175.0 | 40.4 | 10 / 20 | 7TCA297120R0129 - 7TCA297120R0130 |
| EXLLH09* | 63 | 2" | 250.0 | 51.6 | 10 / 20 | 7TCA297120R0131 - 7TCA297120R0132 |

*Add coil length to complete part number e.g. 10 metres = EXLLH10