


EXSLH - High Temp Conduit

LT Metallic Range

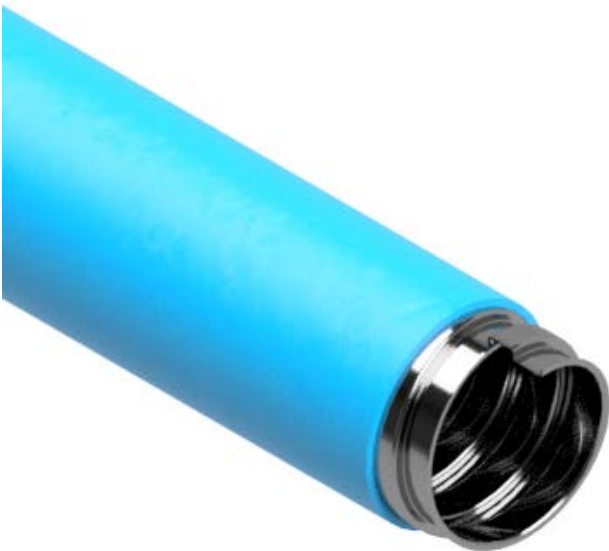

Material

- Co-Polyester Covering
- Stainless Steel Core
- Cotton Packed (03-07)
- Interlocked (08-09)

Features

- Flame Resistant
- Chemical and Oil Resistant
- UL94 V2

Approvals



Certification & Standards

Approved to:	IEC61386-1, 61386-23
Type Examination Certificates:	Must be used with HA-G1 fittings in approved Zones May be used with Ex LT fittings in safe areas
Temperature:	Static -50°C to +130°C Dynamic -5°C to +90°C

Compatible with: EXQ*, EXS*, EXR*, HA-G1 Fittings / Colour: Blue

Part No.	Conduit Size		Static Bend Radius (mm)	Inside Diameter (mm)	Coil Length (m)	GiD Codes
	Metric (mm)	US Trade (Inch)				
EXSLH03*	16	3/8"	50.0	12.5	10 / 30	7TCA297120R0443 - 7TCA297120R0440
EXSLH04*	20	1/2"	75.0	16.0	10 / 30	7TCA297120R0444 - 7TCA297120R0441
EXSLH05*	25	3/4"	90.0	21.0	10 / 30	7TCA297120R0442 - 7TCA297120R0445
EXSLH06*	32	1"	110.0	26.4	10 / 20	7TCA297120R0288 - 7TCA297120R0468
EXSLH07*	40	1-1/4"	130.0	35.3	10 / 20	7TCA297120R0467 - 7TCA297120R0473
EXSLH08*	50	1-1/2"	175.0	40.4	10 / 20	7TCA297120R0455 - 7TCA297120R0469
EXSLH09*	63	2"	250.0	51.6	10 / 20	7TCA297120R0474 - 7TCA297120R0475

*Add coil length to complete part number e.g. 10 metres = EXSLH10