


BEH Conduit Clip Ex e Non Metallic System

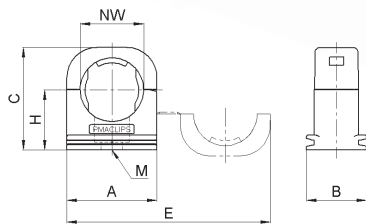

Features

- Prevents electrostatic charging
- For indoor and outdoor applications
- Easy installation
- Very good chemical properties

Approvals



Certification & Standards

Approved to:	IEC EN 60079-0, 60079-7, 60079-31
EC TYPE Examination Certificate:	ATEX: SEV 15 ATEX 0107X IECEX: IECEX SEV15.0001X Ex e IIC Gb Ex tb IIIC Db
Temperature:	-5°C to +85°C Sizes 02-03 -20°C to +85°C Sizes 04-08
IP protection:	IP68

Compatible with: XESX and EXB Conduit / Materials: Anti-Static Nylon 12 / Colour: ● Black

Part No.	Conduit Size (mm)		Dimensions (mm)						Weight kg/100	GID Codes
	Metric	NW	A	B	C	H	E	M		
BEH02	12	10	20.5	20	24.5	15.5	47.5	M5	0.4	7TCA297120R0412
BEH03	16	12	24	20	27	16.5	54.5	M5	0.6	7TCA297120R0413
BEH04	20	17	30	20	34	20	68	M6	0.8	7TCA297120R0414
BEH05	25	23	38.5	20	42	24	85	M6	1.1	7TCA297120R0415
BEH06	32	29	45.5	20	48	27	99	M6	1.5	7TCA297120R0416
BEH07	40	36	55.5	20	56	31	119	M6	1.9	7TCA297120R0417
BEH07	50	48	67.5	20	68	37	143	M6	2.6	7TCA297120R0418

