


PRODUCT-DETAILS

3BDH000610R1

CAC 10-P, Closed Loop Control

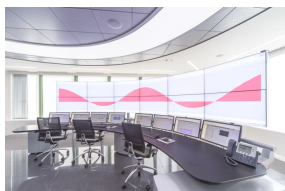

General Information

Product ID	3BDH000610R1
ABB Type Designation	3BDH000610
Catalog Description	CAC 10-P, Closed Loop Control CAC 10-P, Closed Loop Control, SW Version as from 1.61
Long Description	4 Channels, Transmitter Power Supply, - Coupling Relay Control, Connection of Servo Drives, - Actuators and Pneumatics PI-Step Control, - Three-Point-Positioner - Necessary Accessories: 4 pcs. CI 100/101, 1 Cable Clamp

Additional Information

Medium Description	4 Channels, Transmitter Power Supply, - Coupling Relay Control, Connection of Servo Drives, - Actuators and Pneumatics PI-Step Control, - Three-Point-Positioner - Necessary Accessories: 4 pcs. CI 100/101, 1 Cable Clamp
Product Type	I-O Module

Ordering

HS Code	853890-- Parts suitable for use solely or principally with the apparatus of heading 85.35, 85.36 or 85.37.- Other
Customs Tariff Number	85389099

Dimensions	
Product Net Depth / Length	202 mm
Product Net Height	340 mm
Product Net Width	45 mm
Product Net Weight	0.62 kg

Technical	
Channel Type	AX DX
Number of Input Channels	24
Number of Output Channels	20

Environmental	
RoHS Status	Following EU Directive 2011/65/EU
WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
Number of Batteries	0
SCIP	1a119b24-c448-472e-ac31-bf61c6262791 Malta (MT)

Categories	
Control System Products → I/O Products → S+ MR I/O → S+ MR I/O - Modules → CAC 10-P, Closed Loop Ctrl	
Control Systems → Symphony Plus → I/Os → MR Series (Melody Rack) I/O → CAC 10-P	

