


PRODUCT-DETAILS

3BDH000735R1

CFI 10-P, Frequency Input

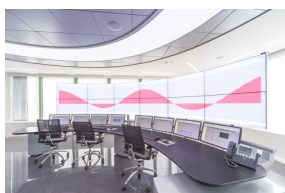

General Information

Product ID	3BDH000735R1
ABB Type Designation	3BDH000735
Catalog Description	CFI 10-P, Frequency Input
	CFI 10-P, Frequency Input, SW Version as from 1.61
Long Description	4 channels , galvanic isolation per channel, - Transmitter supply - Initiators (Namur, 3-Wire), Contact Scanning, - Outputs with int/ext. Supply - Dosing circuit, Frequency input, - Necessary Accessories: 4 pcs. CI 100 / CI 101, Cable Clamp

Additional Information

Medium Description	4 channels , galvanic isolation per channel, - Transmitter supply - Initiators (Namur, 3-Wire), Contact Scanning, - Outputs with int/ext. Supply - Dosing circuit, Frequency input, - Necessary Accessories: 4 pcs. CI 100 / CI 101, Cable Clamp
Product Type	I-O_Module

Ordering

HS Code	853890-- Parts suitable for use solely or principally with the apparatus of
---------	---

	heading 85.35, 85.36 or 85.37.- Other
Customs Tariff Number	85389099

Dimensions

Product Net Depth / Length	204 mm
Product Net Height	340 mm
Product Net Width	45 mm
Product Net Weight	0.7 kg

Technical

Channel Type	DI
Number of Input Channels	12
Number of Output Channels	8

Environmental

RoHS Status	Following EU Directive 2011/65/EU and Amendment 2015/863 July 22, 2019
WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
Number of Batteries	0
SCIP	a6e8faf8-3f78-4de8-b745-21ad1af5d355 Germany (DE)

Categories

Control System Products → I/O Products → S+ MR I/O → S+ MR I/O - Modules → CFI 10-P, Frequency In
Control Systems → Symphony Plus → I/Os → MR Series (Melody Rack) I/O → CFI 10-P

