


PRODUCT-DETAILS

# 3GAA093520-BGE

## (3GAA093520-BGE)

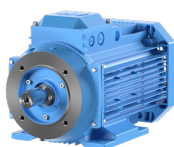

### General Information

Product ID	3GAA093520-BGE
ABB Type Designation	M3AA 90LB 6
Catalog Description	(3GAA093520-BGE)

### Ordering

ABB Type Designation	M3AA 90LB 6
Invoice Description	M3AA 90LB 6
Product Name	3-Phase squirrel cage motor
Product Type	3AA2__M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI)
Customs Tariff Number	85015220
Replaced Product ID (OLD)	3GAA093443-BGE

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	IS/IN
Y	--	50 Hz	415 V	0.75 kW	935 r/min	1.93 A	0.710	76.10 %	4.10
Temperature Class Default									--
Altitude									1000 m
Ambient Temperature									40 °C
IC Class									IC411
IE Class Data (50 Hz)									IE Class IE2 Full Load (100%) 76.1 % Partial Load (75%) 76.0 % Partial Load (50%) 72.7 %
IP Class									IP55
Insulation Class									ICLF
Direction of Rotation									Both sides
Number of Poles (High)									6
Two Speed Motor									No
Type of Duty									S1
Voltage Code									G

Mechanical

Frame Material	Aluminum
Frame Size	90
Bearing	6205-2Z/C3
Bearing NDE	6204-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	18 kg
Gross Weight	21 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

---

## Categories

---

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

