


PRODUCT-DETAILS

3GAA098504-BHF

(3GAA098504-BHF)

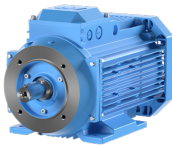

General Information	
Product ID	3GAA098504-BHF
ABB Type Designation	M3AA 90L 4/6
Catalog Description	(3GAA098504-BHF)

Ordering	
ABB Type Designation	M3AA 90L 4/6
Invoice Description	M3AA 90L 4/6
Product Name	3-Phase squirrel cage motor
Product Type	3AA2__M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI)
Customs Tariff Number	85015220
Replaced Product ID (OLD)	3GAA098205-BHE

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque	IS/IN
Y	--	50 Hz	415 V	1.50 kW	1416 r/min	3.40 A	0.820	73.60 %	10.10 N·m	4.60
Y	--	50 Hz	415 V	0.45 kW	936 r/min	1.70 A	0.700	52.00 %	4.60 N·m	3.00
Temperature Class										--
Default										
Altitude										1000 m
Ambient Temperature										40 °C
IC Class										IC411
IE Class Data (50 Hz)										IE Class NA Full Load (100%) 52.0 % Partial Load (75%) 51.4 % Partial Load (50%) 45.9 %
IP Class										IP55
Insulation Class										ICLF
Direction of Rotation										Both sides
Number of Poles (High)										4
Two Speed Motor										Yes
Type of Duty										S1
Voltage Code										H

Mechanical

Frame Material	Aluminum
Frame Size	90
Bearing	6205-2Z/C3
Bearing NDE	6204-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	16 kg
Gross Weight	19 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

Categories

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

