




PRODUCT-DETAILS

3GAA099108-ADF  
(3GAA099108-ADF)

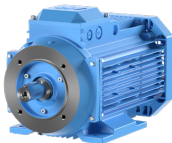

General Information	
Product ID	3GAA099108-ADF
ABB Type Designation	M3AA 90S 2-4
Catalog Description	(3GAA099108-ADF)

Ordering	
ABB Type Designation	M3AA 90S 2-4
Invoice Description	M3AA 90S 2-4
Product Name	3-Phase squirrel cage motor
Product Type	3AA2_M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI) Poland (PL)
Customs Tariff Number	85015220
Replaced Product ID (OLD)	3GAA098110-ADE

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque	IS/IN
YY	--	50 Hz	400 V	1.30 kW	2730 r/min	3.10 A	0.880	71.00 %	4.50 N·m	3.90
D	--	50 Hz	400 V	1.00 kW	1400 r/min	2.60 A	0.800	71.00 %	6.80 N·m	3.80

Temperature Class	--
Altitude	1000 m
Ambient Temperature	40 °C
IC Class	IC411
IE Class Data (50 Hz)	IE Class NA Full Load (100%) 71.0 % Partial Load (75%) 69.2 % Partial Load (50%) 64.5 %
IP Class	IP55
Insulation Class	ICLF
Direction of Rotation	Both sides
Number of Poles (High)	2
Two Speed Motor	Yes
Type of Duty	S1
Voltage Code	D

Mechanical

Frame Material	Aluminum
Frame Size	90
Bearing	6205-2Z/C3
Bearing NDE	6204-2Z/C3
IM Class	IMB3 IM1001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	13 kg
Gross Weight	16 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

---

## Categories

---

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

