


PRODUCT-DETAILS

3GAA108508-BDF  
(3GAA108508-BDF)

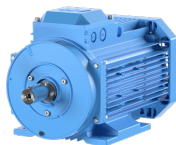

General Information

Product ID	3GAA108508-BDF
ABB Type Designation	M3AA 100L 2-4
Catalog Description	(3GAA108508-BDF)

Ordering

ABB Type Designation	M3AA 100L 2-4
Invoice Description	M3AA 100L 2-4
Product Name	3-Phase squirrel cage motor
Product Type	3AA2_M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI) Poland (PL)
Customs Tariff Number	85015220
Replaced Product ID (OLD)	3GAA108101-BDE

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque	IS/IN
YY	--	50 Hz	400 V	3.00 kW	2880 r/min	6.20 A	0.890	81.00 %	9.90 N·m	6.30
Y	--	50 Hz	400 V	0.60 kW	1470 r/min	1.90 A	0.610	74.00 %	3.90 N·m	4.80
Temperature Class Default										--
Altitude										1000 m
Ambient Temperature										40 °C
IC Class										IC411
IE Class Data (50 Hz)										IE Class NA Full Load (100%) 74.0 % Partial Load (75%) 67.6 % Partial Load (50%) 62.0 %
IP Class										IP55
Insulation Class										ICLF
Direction of Rotation										Both sides
Number of Poles (High)										2
Two Speed Motor										Yes
Type of Duty										S1
Voltage Code										D

Mechanical

Frame Material	Aluminum
Frame Size	100
Bearing	6306-2Z/C3
Bearing NDE	6205-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	21 kg
Gross Weight	26 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

---

## Categories

---

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

