


PRODUCT-DETAILS

3GAA132300-BHE

(3GAA132300-BHE)

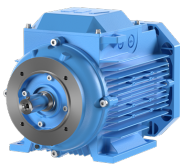

General Information	
Product ID	3GAA132300-BHE
ABB Type Designation	M3AA 132M 4
Catalog Description	(3GAA132300-BHE)

Ordering	
ABB Type Designation	M3AA 132M 4
Invoice Description	M3AA 132M 4
Product Name	3-Phase squirrel cage motor
Product Type	3AA2_M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI)
Customs Tariff Number	85015220
Replaced Product ID (OLD)	3GAA132442-BHE

Electrical

Electrical Data										
Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	IS/IN	
D	--	50 Hz	415 V	5.50 kW	1465 r/min	10.70 A	0.800	88.80 %	6.50	
Temperature Class Default										--
Altitude										1000 m
Ambient Temperature										40 °C
IC Class										IC411
IE Class Data (50 Hz)										IE Class IE2 Full Load (100%) 88.8 % Partial Load (75%) 89.1 % Partial Load (50%) 87.9 %
IP Class										IP55
Insulation Class										ICLF
Direction of Rotation										Both sides
Number of Poles (High)										4
Two Speed Motor										No
Type of Duty										S1
Voltage Code										H

Mechanical

Frame Material	Aluminum
Frame Size	132
Bearing	6208-2Z/C3
Bearing NDE	6206-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	48 kg
Gross Weight	53 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

Categories

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

