




PRODUCT-DETAILS

3GAA132310-BDJ

IE3 Premium Efficiency Aluminum Motors, 7.5 kW, 400 V (3GAA132310-BDJ)

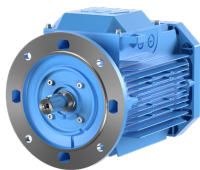

General Information										
Product ID							3GAA132310-BDJ			
ABB Type Designation							M3AA 132MA 4			
Catalog Description							IE3 Premium Efficiency Aluminum Motors, 7.5 kW, 400 V (3GAA132310-BDJ)			

Electrical Data										
Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque	IS/IN
Y	--	50 Hz	690 V	7.50 kW	1462 r/min	9.00 A	0.790	90.60 %	48.90 N·m	6.70
D	--	50 Hz	400 V	7.50 kW	1462 r/min	15.60 A	0.790	90.60 %	48.90 N·m	6.70
D	--	50 Hz	415 V	7.50 kW	1464 r/min	15.60 A	0.760	90.60 %	48.80 N·m	7.00

Ordering										
Country of Origin							China (CN) Finland (FI) Poland (PL)			

Customs Tariff Number	85015220
Selling Unit of Measure	piece
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Stocked At (Warehouses)	Espoo, Finland Vittuone, Italy

Dimensions

Product Net Weight	59 kg
--------------------	-------

Additional Information

Product Name	3-Phase squirrel cage motor
--------------	-----------------------------

Categories

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE3 Premium Efficiency Aluminum Motors
Motors and Generators → Service → Spares and Consumables → Parts

