


PRODUCT-DETAILS

3GAA133330-BHE (3GAA133330-BHE)

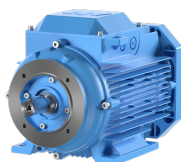

General Information

Product ID	3GAA133330-BHE
ABB Type Designation	M3AA 132MC 6
Catalog Description	(3GAA133330-BHE)

Ordering

ABB Type Designation	M3AA 132MC 6
Invoice Description	M3AA 132MC 6
Product Name	3-Phase squirrel cage motor
Product Type	3AA2_M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI)
Customs Tariff Number	85015220
Replaced Product ID (OLD)	3GAA133444-BHE

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	IS/IN
D	--	50 Hz	415 V	5.50 kW	975 r/min	12.60 A	0.680	88.70 %	5.60
Temperature Class Default									
									--
Altitude									1000 m
Ambient Temperature									40 °C
IC Class									IC411
IE Class Data (50 Hz)									IE Class IE2
									Full Load (100%) 88.7 %
									Partial Load (75%) 88.6 %
									Partial Load (50%) 87.0 %
IP Class									IP55
Insulation Class									ICLF
Direction of Rotation									Both sides
Number of Poles (High)									6
Two Speed Motor									No
Type of Duty									S1
Voltage Code									H

Mechanical

Frame Material	Aluminum
Frame Size	132
Bearing	6208-2Z/C3
Bearing NDE	6206-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	59 kg
Gross Weight	64 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

Categories

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

