


PRODUCT-DETAILS

3GAA208412-BDG

(3GAA208412-BDG)

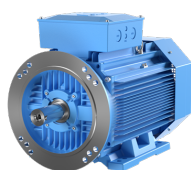

General Information

Product ID	3GAA208412-BDG
ABB Type Designation	M3AA 200MLA 4/8
Catalog Description	(3GAA208412-BDG)

Ordering

ABB Type Designation	M3AA 200MLA 4/8
Invoice Description	M3AA 200MLA 4/8
Product Name	3-Phase squirrel cage motor
Product Type	3AA2__M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI)
Customs Tariff Number	85015230
Replaced Product ID (OLD)	3GAA208246-BDG

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque	IS/IN
D	--	50 Hz	400 V	26.00 kW	1483 r/min	49.10 A	0.840	90.90 %	167.00 N·m	7.50
D	--	50 Hz	400 V	3.30 kW	742 r/min	11.40 A	0.540	76.90 %	42.00 N·m	5.10

Temperature Class	--
Default	
Altitude	1000 m
Ambient Temperature	40 °C
IC Class	IC411
IE Class Data (50 Hz)	IE Class NA Full Load (100%) 76.9 % Partial Load (75%) 75.3 % Partial Load (50%) 70.3 %
IP Class	IP55
Insulation Class	ICLF
Direction of Rotation	Both sides
Number of Poles (High)	4
Two Speed Motor	Yes
Type of Duty	S1
Voltage Code	D

Mechanical

Frame Material	Aluminum
Frame Size	200
Bearing	6312-2Z/C3
Bearing NDE	6210-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 pallet (lift)
Product Net Weight	218 kg
Gross Weight	228 kg

Environmental

WEEE Category	4. Large Equipment (Any External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

Categories

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

