


## PRODUCT-DETAILS

# 3GAA209418-BDG (3GAA209418-BDG)

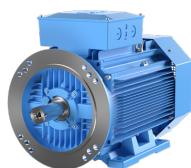

### General Information

Product ID	3GAA209418-BDG
ABB Type Designation	M3AA 200MLA 2-4
Catalog Description	(3GAA209418-BDG)

### Ordering

ABB Type Designation	M3AA 200MLA 2-4
Invoice Description	M3AA 200MLA 2-4
Product Name	3-Phase squirrel cage motor
Product Type	3AA2_M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI)
Customs Tariff Number	85015230
Replaced Product ID (OLD)	3GAA208121-BDG

### Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque	IS/IN
YY	--	50 Hz	400 V	32.00 kW	2957 r/min	57.00 A	0.900	90.00 %	103.00 N·m	7.00
D	--	50 Hz	400 V	24.00 kW	1476 r/min	44.80 A	0.850	90.90 %	155.00 N·m	6.70

Temperature Class Default	--
Altitude	1000 m
Ambient Temperature	40 °C
IC Class	IC411
IE Class Data (50 Hz)	IE Class NA Full Load (100%) 90.0 % Partial Load (75%) 91.0 % Partial Load (50%) 90.3 %
IP Class	IP55
Insulation Class	ICLF
Direction of Rotation	Both sides
Number of Poles (High)	2
Two Speed Motor	Yes
Type of Duty	S1
Voltage Code	D

Mechanical

Frame Material	Aluminum
Frame Size	200
Bearing	6312-2Z/C3
Bearing NDE	6210-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 pallet (lift)
Product Net Weight	218 kg
Gross Weight	228 kg

Environmental

WEEE Category	4. Large Equipment (Any External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

---

## Categories

---

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

