


PRODUCT-DETAILS

3GAA229228-BDG (3GAA229228-BDG)

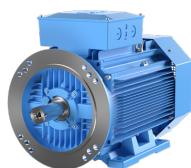

General Information

Product ID	3GAA229228-BDG
ABB Type Designation	M3AA 225SMB 2-4
Catalog Description	(3GAA229228-BDG)

Ordering

ABB Type Designation	M3AA 225SMB 2-4
Invoice Description	M3AA 225SMB 2-4
Product Name	3-Phase squirrel cage motor
Product Type	3AA2_M3AA_IE2_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Finland (FI)
Customs Tariff Number	85015290
Replaced Product ID (OLD)	3GAA228122-BDG

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque	IS/IN
YY	--	50 Hz	400 V	50.00 kW	2964 r/min	85.70 A	0.910	92.50 %	161.00 N·m	7.00
D	--	50 Hz	400 V	40.00 kW	1478 r/min	71.00 A	0.880	92.30 %	2589.00 N·m	5.90

Temperature Class Default	--
Altitude	1000 m
Ambient Temperature	40 °C
IC Class	IC411
IE Class Data (50 Hz)	IE Class NA Full Load (100%) 92.3 % Partial Load (75%) 83.4 % Partial Load (50%) 93.5 %
IP Class	IP55
Insulation Class	ICLF
Direction of Rotation	Both sides
Number of Poles (High)	2
Two Speed Motor	Yes
Type of Duty	S1
Voltage Code	D

Mechanical

Frame Material	Aluminum
Frame Size	225
Bearing	6313-2Z/C3
Bearing NDE	6212-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 pallet (lift)
Product Net Weight	287 kg
Gross Weight	297 kg

Environmental

WEEE Category	4. Large Equipment (Any External Dimension More Than 50 cm)
SCIP	27ac6190-e1ce-4080-8654-6552aaabbe58 Finland (FI)

Classifications

UNSPSC	26101100
--------	----------

Categories

Motors and Generators → IEC Low Voltage AC Motors → Process Performance Motors → IE2 High Efficiency Aluminum Motors

