


PRODUCT-DETAILS

3GAL132233-ASB  
M3AL 132SMC 4

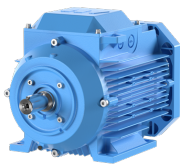

General Information	
Product ID	3GAL132233-ASB
ABB Type Designation	M3AL 132SMC 4
Catalog Description	M3AL 132SMC 4

Ordering	
ABB Type Designation	M3AL 132SMC 4
Invoice Description	M3AL 132SMC 4
Product Name	3Phase Synchronous reluctance motor
Product Type	3AL0__M3AL_SynRM_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Sweden (SE)
Customs Tariff Number	85014080
Replaced Product ID (OLD)	3GAL132007-ASB
Stocked At (Warehouses)	Menden, Germany

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque
Y	--	50 Hz	400 V	11.00 kW	1500 r/min	25.00 A	0.750	89.80 %	70.00 N·m
Temperature Class Default									--
Altitude									1000 m
Ambient Temperature									40 °C
IC Class									IC411
IE Class Data (50 Hz)									IE Class IE2 Full Load (100%) 89.8 % Partial Load (75%) 89.9 % Partial Load (50%) 89.0 %
IP Class									IP55
Insulation Class									ICLF
Direction of Rotation									Both sides
Number of Poles (High)									4
Two Speed Motor									No
Type of Duty									S9
Voltage Code									S

Mechanical

Frame Material	Aluminum
Frame Size	132
Bearing	6308-2Z/C3
Bearing NDE	6206-2Z/C3
IM Class	IMB3 IM1001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	57 kg
Gross Weight	62 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
---------------	--

Classifications

UNSPSC	26101100
--------	----------

---

## Categories

---

Motors and Generators → IEC Low Voltage AC Motors → Synchronous Reluctance Motors → High Output SynRM Motors

