


PRODUCT-DETAILS

3GAL132237-BSB
M3AL 132SMC 4

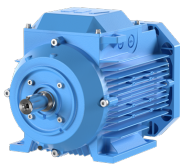

General Information

Product ID	3GAL132237-BSB
ABB Type Designation	M3AL 132SMC 4
Catalog Description	M3AL 132SMC 4

Ordering

ABB Type Designation	M3AL 132SMC 4
Invoice Description	M3AL 132SMC 4
Product Name	3Phase Synchronous reluctance motor
Product Type	3AL0_M3AL_SynRM_AA
Made To Order	No
Minimum Order Quantity	1 piece
Order Multiple	1 piece
Selling Unit of Measure	piece
Country of Origin	Sweden (SE)
Customs Tariff Number	85015230
Replaced Product ID (OLD)	3GAL132002-BSB
Stocked At (Warehouses)	Menden, Germany

Electrical

Electrical Data

Conn	Temp Class	Freq	Voltage	Power	Speed	Current	Power Factor	Efficiency	Torque
Y	--	50 Hz	400 V	18.50 kW	3000 r/min	41.10 A	0.750	92.40 %	58.90 N·m
Temperature Class									
Default									
Altitude									
1000 m									
Ambient Temperature									
40 °C									
IC Class									
IC411									
IE Class Data (50 Hz)									
IE Class IE3									
Full Load (100%) 92.4 %									
Partial Load (75%) 91.8 %									
Partial Load (50%) 90.0 %									
IP Class									
IP55									
Insulation Class									
ICLF									
Direction of Rotation									
Both sides									
Number of Poles (High)									
4									
Two Speed Motor									
No									
Type of Duty									
S9									
Voltage Code									
S									

Mechanical

Frame Material	Aluminum
Frame Size	132
Bearing	6308-2Z/C3
Bearing NDE	6206-2Z/C3
IM Class	IMB5 IM3001
Terminator Box Location	D-End top

Dimensions

Package Level 1 Units	0 carton
Product Net Weight	57 kg
Gross Weight	62 kg

Environmental

WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)
---------------	--

Classifications

UNSPSC	26101100
--------	----------

Categories

Motors and Generators → IEC Low Voltage AC Motors → Synchronous Reluctance Motors → High Output SynRM Motors

